



GRUNDFOS
ECADEMY

PRESSURE BOOSTERS

THE CM BOOSTER WITH PM2

be
think
innovate

GRUNDFOS 

The CM Booster PM2

With a CM Booster PM2, you have the opportunity to adjust the settings according to the application.


Simplified startup pressure settings ensure the right performance for any application, and put the end user firmly in charge.



Applications

The CM Booster with PM2 is designed to boost water supply in domestic applications.

It can connect to city mains either directly or via a break tank.

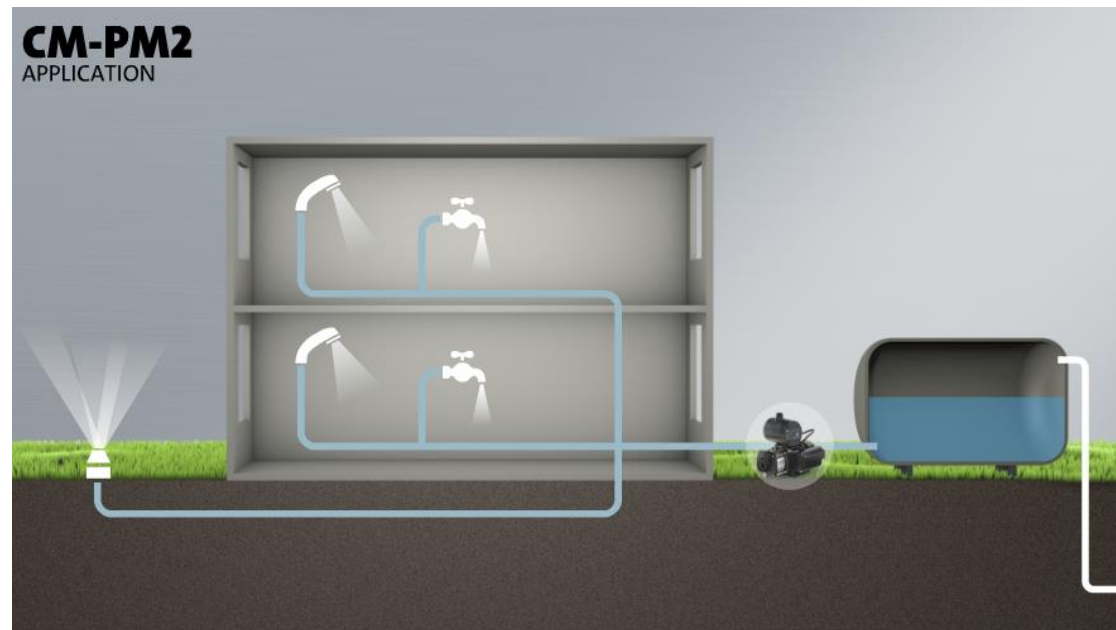


Main benefits

- Automatic start-stop with adjustable settings
- All-in-one system – plug & pump
- Low noise operation ≤ 55 dB(A)
- Suitable for generator operation – power fluctuations
- Dry run & overload protection
- 2-year warranty




Performance

CM1/CM3

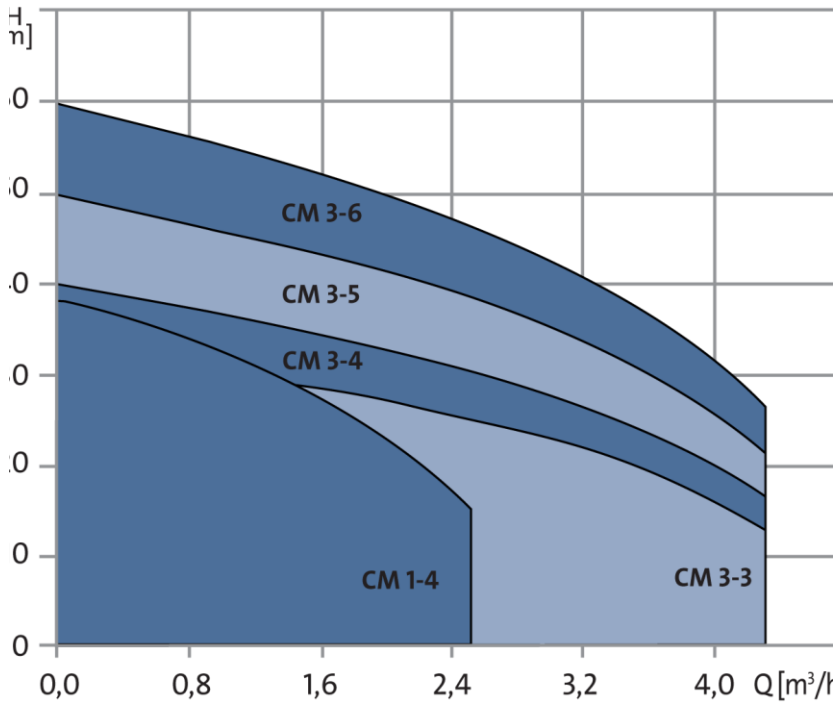

CM5

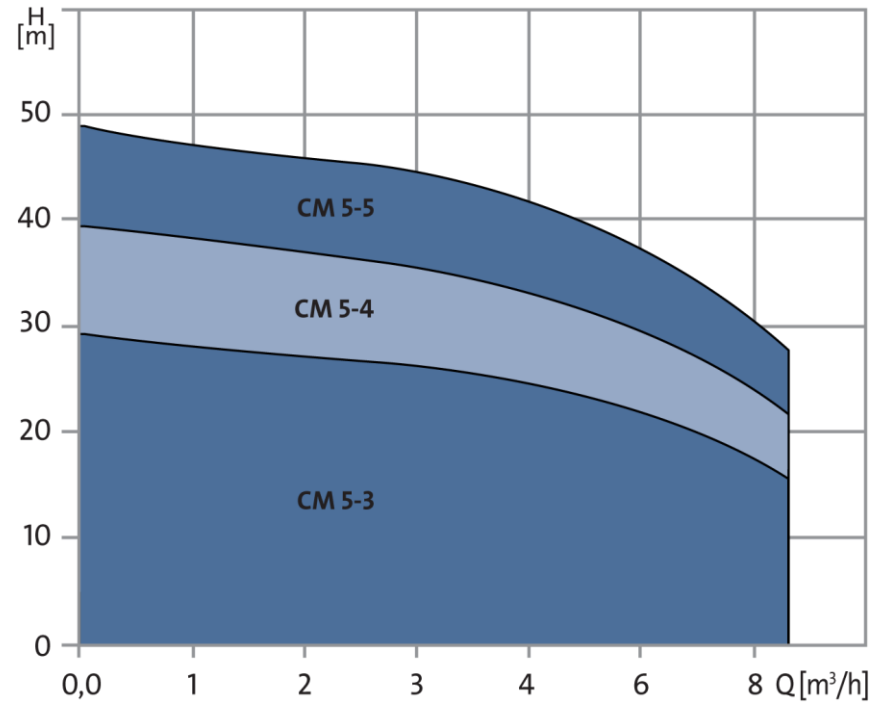

Selection

TAPS		FLOORS			
		1 - 5	6 - 10	11 - 20	21 - 50
	4	CMB 1-6	CMB 3-5	CMB 3-5	CMB 5-5
	3	CMB 1-5	CMB 3-4	CMB 3-5	CMB 5-5
	2	CMB 1-5	CMB 3-4	CMB 3-5	CMB 5-4
	1	CMB 1-4	CMB 3-3	CMB 3-4	CMB 5-4



Technical data

- Mains voltage: 1x 220-240V, 50/60Hz
- Enclosure class: IP55
- Sound pressure level: ≤ 55 dB(A)
- Start/stop frequency: Max. 100 per hour
- Approvals: Drinking water approved



GRUNDFOS **ECADEMY**

www.grundfos.com